


### Outline Dimensions

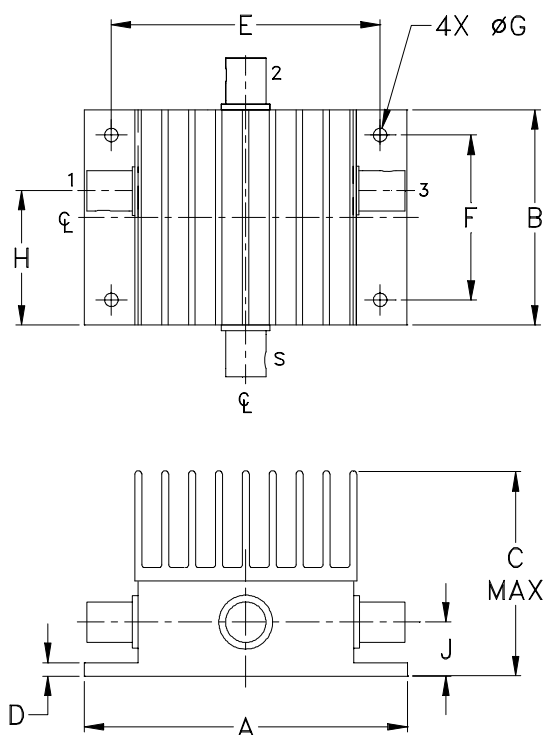

| CASE # | A               | B               | C               | D              | E                | F                | G              | H               | J              | WT. GRAM |
|--------|-----------------|-----------------|-----------------|----------------|------------------|------------------|----------------|-----------------|----------------|----------|
| AX255  | 3.00<br>(76.20) | 2.00<br>(50.80) | 1.92<br>(48.77) | .100<br>(2.54) | 2.500<br>(63.50) | 1.525<br>(38.74) | .125<br>(3.18) | 1.25<br>(31.75) | .50<br>(12.70) | 343      |

Dimensions are in inches (mm). Tolerances: 2Pl.  $\pm .03$ ; 3Pl.  $\pm .015$

#### Notes:

- Case material: Aluminum alloy.
- Case Finish:  
For RoHS Case Styles: Clear chemical conversion coating, non-chrome or trivalent chrome based.
- Heat sink finish: Black anodize.