
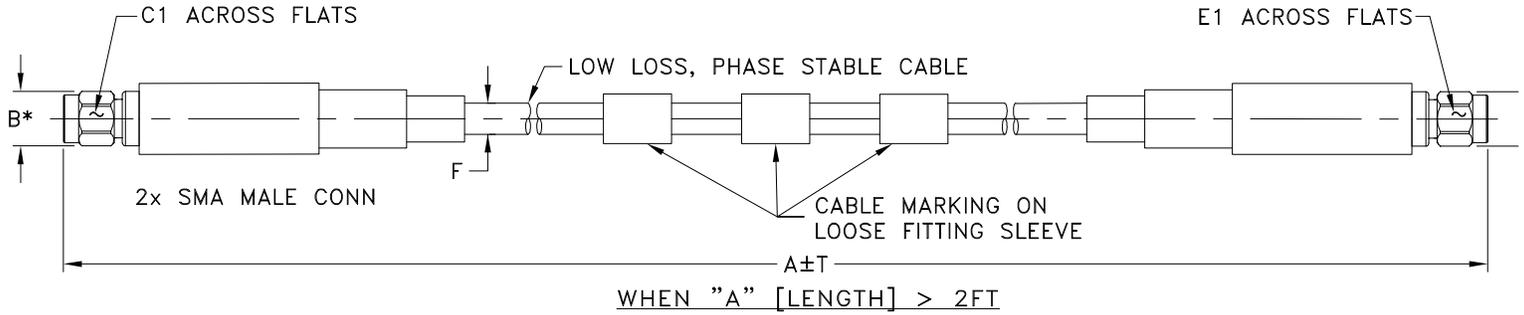


Outline Dimensions

GM3711

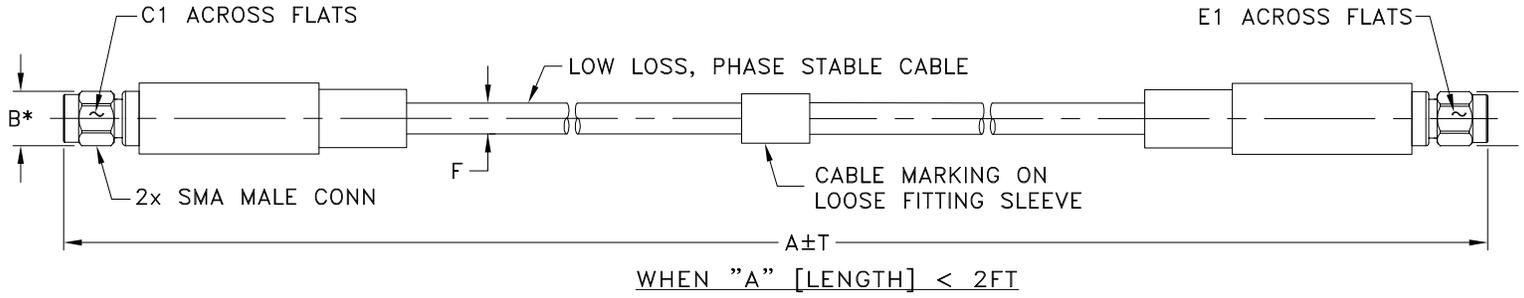

CASE#	A		B	C1	C2	D	E1	E2	F	T		WEIGHT (GRAMS)
	FEET	METERS								FEET	METERS	
GM3711-1	1.00	0.30								+0.04/-0	+0.01/-0	32.0
GM3711-1.5	1.50	0.46								+0.04/-0	+0.01/-0	40.0
GM3711-2	2.00	0.61								+0.04/-0	+0.01/-0	48.5
GM3711-2.5	2.50	0.76								+0.04/-0	+0.01/-0	56.0
GM3711-3	3.00	0.91								+0.06/-0	+0.02/-0	63.5
GM3711-3.28	3.28	1.00	.36	.315	-	.36	.315	-	.205	+0.07/-0	+0.02/-0	68.0
GM3711-3.5	3.50	1.07	(9.14)	(8.00)	-	(9.14)	(8.00)	-	(5.20)	+0.07/-0	+0.02/-0	71.5
GM3711-4	4.00	1.22								+0.08/-0	+0.02/-0	79.0
GM3711-4.92	4.92	1.50								+0.10/-0	+0.03/-0	93.0
GM3711-5	5.00	1.52								+0.10/-0	+0.03/-0	94.0
GM3711-6	6.00	1.83								+0.12/-0	+0.04/-0	109.5
GM3711-6.56	6.56	2.00								+0.13/-0	+0.04/-0	118.0
GM3711-10	10.00	3.05								+0.20/-0	+0.06/-0	170.5
GM3711-15	15.00	4.57								+0.30/-0	+0.09/-0	246.5

Unless Otherwise Specified dimensions are in inches (mm),

Tolerances: 2 Pl. ±0.03; 3 Pl. ±0.015 inches

Notes:

- "A" Represents Length of Cable.
- * OVERALL CONNECTOR DIMENSION [CONNECTOR SHAPE MAY VARY]

Mini-Circuits®
ISO 9001 ISO 14001 CERTIFIED

ALL NEW
minicircuits.com

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: www.minicircuits.com

RF/IF MICROWAVE COMPONENTS