


# Case Style

KP

## Outline Dimensions

KP2341

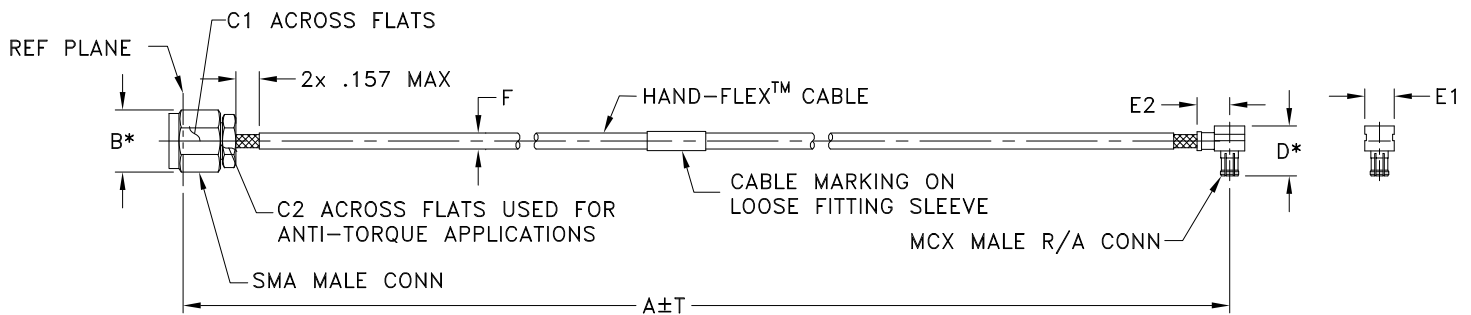

\* OVERALL CONNECTOR DIMENSION  
[CONNECTOR SHAPE MAY VARY]

Case Style #	A		B	C1	C2	D	E1	E2	F		T		WT. (GRAMS)
	INCH	MM							086U-ASMMCR+	086-ASMMCR+	INCH	MM	
KP2341-12	12.00	304.80	.36 [9.14]	.315 [8.00]	.250 [6.35]	.338 [8.6]	.197 [5.00]	.22 [5.6]	.091 MAX [2.31 MAX]	.123 MAX [3.12 MAX]	.10	2.54	8.98

Unless Otherwise Specified dimensions are in inches [mm],  
Tolerances: 2 Pl. ±0.03; 3 Pl. ±0.015 inches

Notes:

1. 086 Hand-Flex™ Coaxial Cable.
2. "A" Represents Length of Cable.

**Mini-Circuits®**  
ISO 9001 ISO 14001 CERTIFIED

ALL NEW  
minicircuits.com

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: [www.minicircuits.com](http://www.minicircuits.com)

RF/IF MICROWAVE COMPONENTS