


Case Style

KP

Outline Dimensions

KP3757

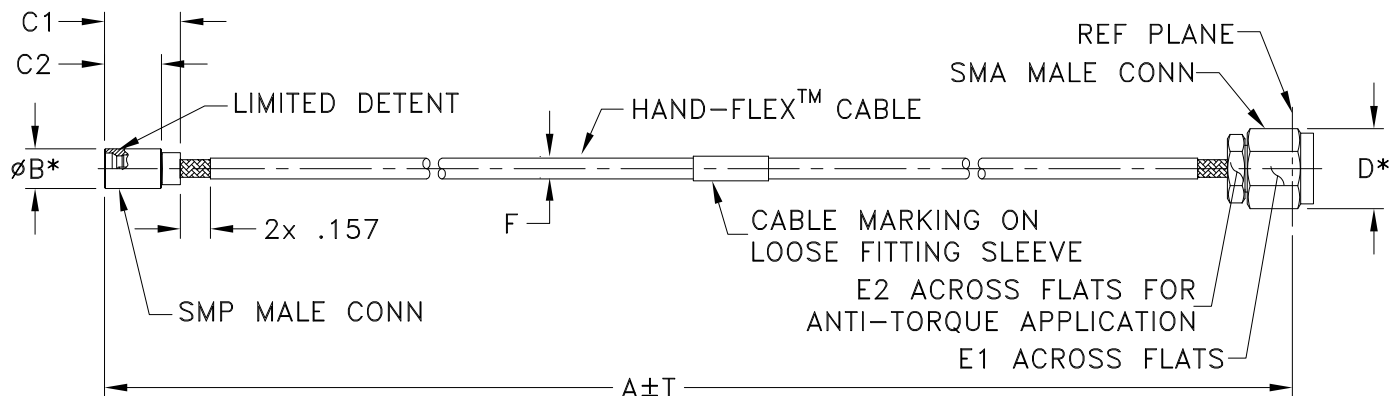

* OVERALL CONNECTOR DIMENSION
[CONNECTOR SHAPE MAY VARY]

Case Style #	A		B	C1	C2	D	E1	E2	F		T		WT. (GRAMS)
	INCH	MM							086U-ASMPMSM+ 086UCU-ASMPMSM+	086-ASMPMSM+ 086CU-ASMPMSM+	INCH	MM	
KP3825-3.94	3.94	100.00	.18 [4.60]	.346 [8.80]	.260 [6.60]	.36 [9.14]	.315 [8.00]	.250 [6.35]	.091 MAX [2.31 MAX]	.123 MAX [3.12 MAX]	.05	1.27	5.90
KP3823-7.87	7.87	200.00									.10	2.54	7.50
KP3823-11.8	11.81	300.00									.10	2.54	9.10
KP3823-19.7	19.69	500.00									.15	3.81	12.31

Unless Otherwise Specified dimensions are in inches [mm],
Tolerances: 2 Pl. ±0.03; 3 Pl. ±0.015 inches

Notes:

1. 086 Hand-Flex™ Coaxial Cable.
2. "A" Represents Length of Cable.

Mini-Circuits®
ISO 9001 ISO 14001 CERTIFIED

ALL NEW
minicircuits.com

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: www.minicircuits.com

RF/IF MICROWAVE COMPONENTS