


Outline Dimensions

ND1920

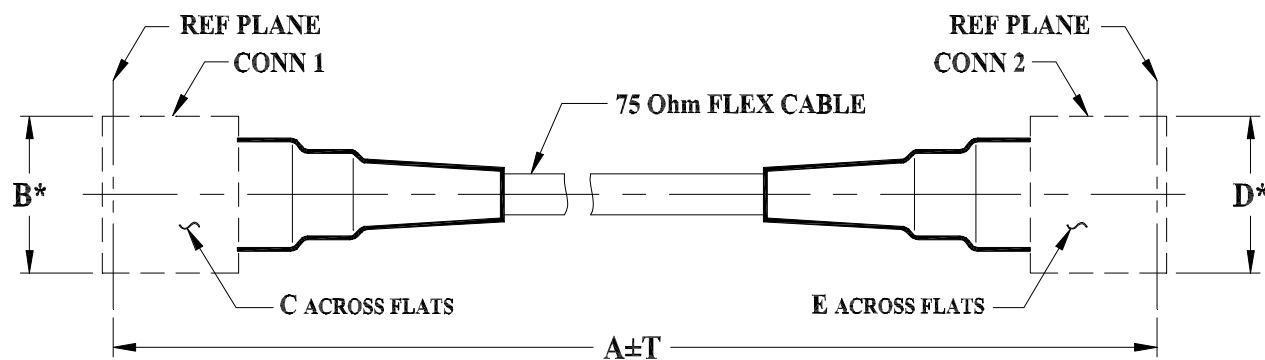

* OVERALL CONNECTOR OR CABLE & BOOT DIMENSION
(CONNECTOR SHAPE MAY VARY)

ND1919 SERIES

N MALE 75 Ohm (CONN-1)

N MALE 75 Ohm (CONN-2)

CASE STYLE #	A		B	C	D	E	T		WEIGHT GRAMS
	FEET	METERS					FEET	METERS	
ND1920-3	3.00	.91	.81 (20.57)	.750 (19.05)	.81 (20.57)	.750 (19.05)	.09	.03	128
ND1920-6	6.00	1.83					.18	.05	185

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2Pl. $\pm .03$; 3Pl. $\pm .015$

Note:

- 75 Ohm Flexible Coaxial Cable.

Mini-Circuits[®]

INTERNET <http://www.minicircuits.com>

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661

Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010

Mini-Circuits ISO 9001 & ISO 14001 Certified