


## Outline Dimensions

NG1942

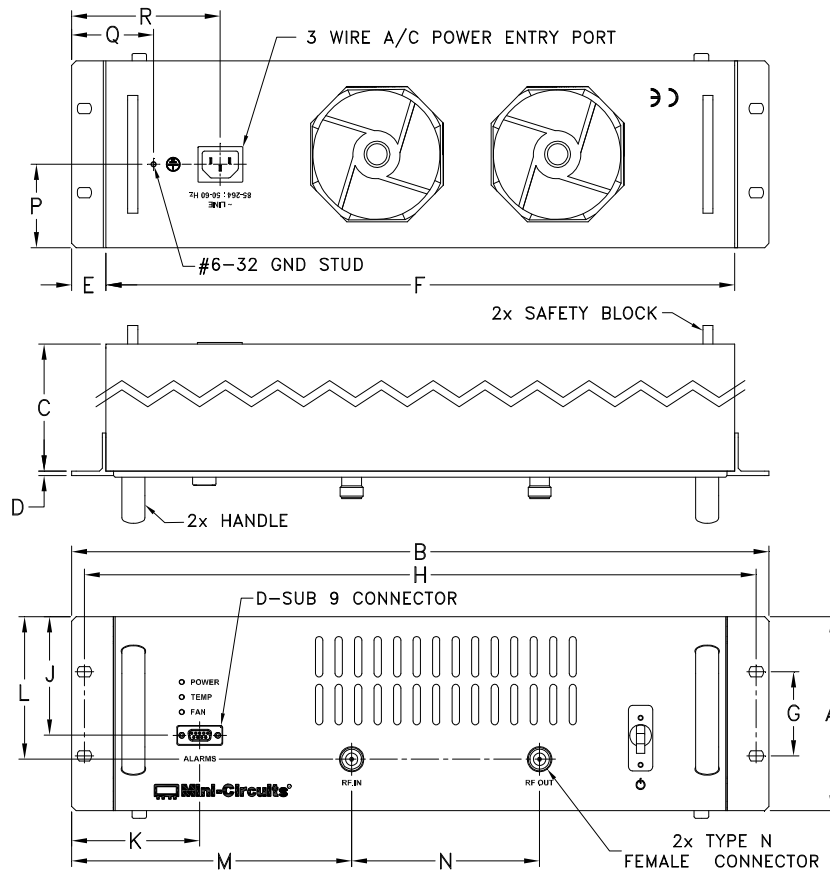

CASE #	A	B	C	D	E	F	G	H	J	K	L
NG1942	5.20 (132.08)	19.00 (482.60)	20.00 (508.00)	.13 (3.30)	.94 (23.88)	17.13 (435.10)	2.25 (57.15)	18.31 (465.07)	3.17 (80.52)	3.49 (88.65)	3.82 (97.03)

CASE #	M	N	P	Q	R	S	T	WT, GRAMS
NG1942	7.63 (193.80)	5.12 (130.05)	2.23 (56.64)	2.24 (56.90)	4.05 (102.87)	--	--	13610

Dimensions are in inches (mm). Tolerances: 2Pl.  $\pm .03$ ; 3Pl.  $\pm .015$

### Note:

1. Case material: Aluminum alloy.
2. Finish: Powder coating, Color: White.



INTERNET <http://www.minicircuits.com>  
 P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661  
 Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010  
 Mini-Circuits ISO 9001 & ISO 14001 Certified